


Air preparation unit FRC-3/4-D-7-MIDI-NPT

Part number: 173874

FESTO

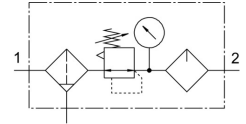

Data sheet

Feature	Value
Size	Midi
Type code	FRC
Mounting position	Vertical
Condensate drain	Manual, non-detenting
Grade of filtration	40 µm
Symbol	00991549
Operating pressure	1 bar ... 16 bar
Pressure regulation range	0.5 bar ... 7 bar
Standard nominal flow rate	2800 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [-:9:-] Inert gas
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Air quality class at the output	Compressed air as per ISO 8573-1:2010 [7:8:-] Inert gas
Temperature of medium	-10 °C ... 60 °C
Ambient temperature	-10 °C ... 60 °C
Product weight	1440 g
Type of mounting	Optionally: Line installation With mounting bracket
Pneumatic connection 1	3/4 NPT
Pneumatic connection 2	3/4 NPT
Note on materials	RoHS-compliant
Housing material	Die-cast zinc
Material of bowl	PC