


# Air preparation unit FRC-3/4-D-7-MAXI-NPT

FESTO

Part number: 173882

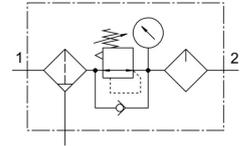

## Data sheet

| Feature                          | Value   |
|----------------------------------|---|
| Size                             | Maxi  |
| Type code                        | FRC   |
| Mounting position                | Vertical  |
| Condensate drain                 | Manually rotating   |
| Grade of filtration              | 40 µm   |
| Symbol                           | 00991761  |
| Operating pressure               | 1 bar ... 16 bar  |
| Standard nominal flow rate       | 8500 l/min  |
| Operating medium                 | Compressed air as per ISO 8573-1:2010 [-:-:-]             |
| Corrosion resistance class (CRC) | 2 - Moderate corrosion stress                             |
| Temperature of medium            | -10 °C ... 60 °C  |
| Ambient temperature              | -10 °C ... 60 °C  |
| Product weight                   | 2390 g  |
| Type of mounting                 | Optionally:<br>Line installation<br>With mounting bracket |
| Pneumatic connection 1           | 3/4 NPT   |
| Pneumatic connection 2           | 3/4 NPT   |
| Housing material                 | Die-cast zinc   |
| Material of bowl                 | PC  |