


Air preparation unit FRC-3/4-D-7-MAXI-A-NPT

FESTO

Part number: 173883

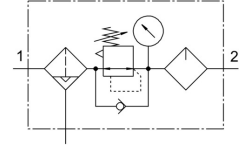

Data sheet

Feature	Value
Size	Maxi
Type code	FRC
Mounting position	Vertical
Condensate drain	Fully automatic
Grade of filtration	40 µm
Symbol	00991599
Operating pressure	2 bar ... 12 bar
Standard nominal flow rate	8500 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [-:-:-]
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Temperature of medium	-10 °C ... 60 °C
Ambient temperature	-10 °C ... 60 °C
Product weight	2390 g
Type of mounting	Optionally: Line installation With mounting bracket
Pneumatic connection 1	3/4 NPT
Pneumatic connection 2	3/4 NPT
Housing material	Die-cast zinc
Material of bowl	PC