


Branching module FRM-3/8-D-MIDI-NPT

Part number: 173927

FESTO

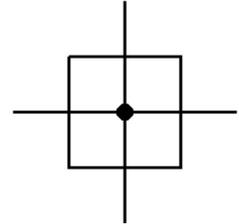

Data sheet

| Feature | Value |
|--|--|
| Type code | FRM |
| Mounting position | Any |
| Structural design | Branching module |
| Symbol | 00991510 |
| Operating pressure | 0 bar ... 16 bar |
| Standard nominal flow rate in main flow direction 1 -> 2 | 6700 l/min |
| Operating medium | Compressed air as per ISO 8573-1:2010 [7:-:-] Inert gas |
| Corrosion resistance class (CRC) | 2 - Moderate corrosion stress |
| Storage temperature | -10 °C ... 60 °C |
| Air quality class at the output | Compressed air as per ISO 8573-1:2010 [7:-:-] Inert gas |
| Temperature of medium | -10 °C ... 60 °C |
| Ambient temperature | -10 °C ... 60 °C |
| Product weight | 522 g |
| Pneumatic connection 1 | 3/8 NPT |
| Pneumatic connection 2 | 3/8 NPT |
| Pneumatic connection 3 | G1/2 |
| Pneumatic connection 4 | G1/4 |
| Note on materials | Free of copper and PTFE RoHS-compliant |
| Housing material | Die-cast aluminum |