


Branching module FRM-3/4-D-MAXI-NPT

Part number: 173930

FESTO

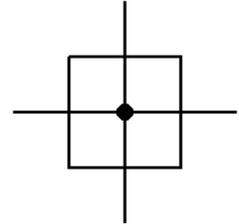

Data sheet

Feature	Value
Type code	FRM
Mounting position	Any
Structural design	Branching module
Symbol	00991510
Operating pressure	0 bar ... 16 bar
Standard nominal flow rate in main flow direction 1 -> 2	20000 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-] Inert gas
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Storage temperature	-10 °C ... 60 °C
Air quality class at the output	Compressed air as per ISO 8573-1:2010 [7:-:-] Inert gas
Temperature of medium	-10 °C ... 60 °C
Ambient temperature	-10 °C ... 60 °C
Product weight	662 g
Pneumatic connection 1	3/4 NPT
Pneumatic connection 2	3/4 NPT
Pneumatic connection 3	G3/4
Pneumatic connection 4	G1/4
Note on materials	Free of copper and PTFE RoHS-compliant
Housing material	Die-cast zinc