
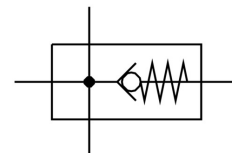


Branching module FRM-H-3/4-D-MAXI-NPT

Part number: 173938

FESTO

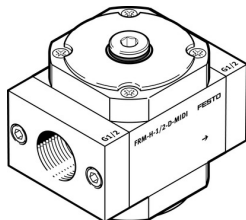

Data sheet

Feature	Value
Type code	FRM
Mounting position	Any
Structural design	Branching module
Symbol	00991511
Operating pressure	0.25 bar ... 16 bar
Standard nominal flow rate in main flow direction 1 -> 2	13500 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-] Inert gas
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Storage temperature	-10 °C ... 60 °C
Air quality class at the output	Compressed air as per ISO 8573-1:2010 [7:-:-] Inert gas
Temperature of medium	-10 °C ... 60 °C
Ambient temperature	-10 °C ... 60 °C
Product weight	666 g
Pneumatic connection 1	3/4 NPT
Pneumatic connection 2	3/4 NPT
Pneumatic connection 3	G3/4
Pneumatic connection 4	G1/4
Note on materials	Free of copper and PTFE RoHS-compliant
Housing material	Die-cast zinc