


Quick coupling EAMD-56-46-25-23X27-U

Part number: 1781045

FESTO

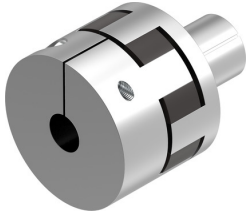

Data sheet

Feature	Value
Diameter of holder 1	25 mm
Diameter of holder 2	23 mm
Size	56
Nominal length	46.5 mm
Type code	EAMD
Mounting position	Any
Max. rotational speed	5500 1/min
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 °C ... 60 °C
Mass moment of inertia	151 kgmm ²
Transferable torque	75 Nm
Product weight	407 g
Note on materials	RoHS-compliant