


Pressure gauge MA-23-6-R1/8

Part number: 183896

FESTO

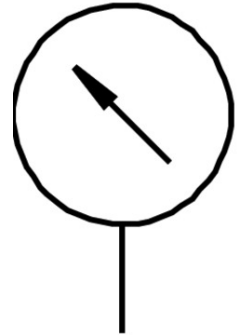

Data sheet

Feature	Value
Display range	0 bar ... 6 bar
Type code	MA
Symbol	00991463
Pressure gauge nominal size	23
Structural design	Bourdon tube pressure gauge
Type of mounting	Line installation
Operating medium	Inert gas Neutral liquids
Operating pressure	0 MPa ... 0.6 MPa
Operating pressure	0 bar ... 6 bar
Operating pressure	0 psi ... 87 psi
Intermittent load factor	0.6
Measurement accuracy class	4
Degree of protection	IP44
Temperature of medium	-20 °C ... 60 °C
Ambient temperature	-20 °C ... 60 °C
Note on materials	RoHS-compliant
Connection position	Centered on rear side
Pneumatic connection	R1/8
Materials in contact with the media	Brass
Material of screwed trunnion	Brass
Housing material	Brass
Inspection window material	PC
Housing colour	Black
Product weight	27 g
Information on operating and pilot media	No acetylene No oxygen