 



Vacuum generator CPV18-M1H-VI140-2GLS-1/4

Part number: 185877

FESTO

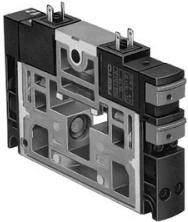

Data sheet

Feature	Value
Nominal width of Laval nozzle	1.4 mm
Type code	CPV18
Mounting position	Any
Ejector characteristics	High vacuum
Symbol	00991561
Operating pressure	2 bar ... 10 bar
Max. vacuum	85 %
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	1 - Low corrosion stress
Temperature of medium	0 °C ... 50 °C
Ambient temperature	0 °C ... 50 °C
Product weight	264 g
Electrical connection	Plug
Type of mounting	With through-hole
Pneumatic connection 1	Sub-base
Pneumatic connection 3	Sub-base
Vacuum connection	G1/4
Note on materials	Free of copper and PTFE RoHS-compliant
Housing material	Die-cast aluminum