


Push-in fitting, self-sealing QSK-G1/2-12

Part number: 186303

FESTO

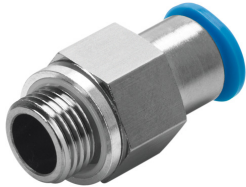

Data sheet

Feature	Value
Size	Standard
Nominal width	6.4 mm
Approved tubing type	PAN- PAN-MF- PAN-R- PAN-VO- PEN- PFAN- PLN- PTFEN- PUN- PUN-CM- PUN-DUO- PUN-H- PUN-H-DUO- PUN-S- PUN-S-DUO- PUN-VO-
Tubing insertion depth	23.1 mm
Type code	QSK
Type of seal on screwed trunnion	Sealing ring
Mounting position	Any
Pack size	1
Structural design	Push-pull principle
Operating pressure for entire temperature range	-0.95 bar ... 6 bar
Temperature-dependent operating pressure	-0.95 bar ... 14 bar
Maritime classification	See certificate
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Information on operating and pilot media	Operation with oil lubrication possible
Corrosion resistance class (CRC)	1 - Low corrosion stress
Ambient temperature	-10 °C ... 80 °C
Nominal tightening torque	26 Nm
Tolerance for nominal tightening torque	± 20%
Product weight	78 g
Pneumatic connection 1	External thread G1/2
Pneumatic connection 2	for pneumatic tubing outside diameter 12 mm
Releasing ring color	Blue
Note on materials	RoHS-compliant
Housing material	Brass Nickel-plated

Feature	Value
Releasing ring material	POM
Material of tubing seal	NBR
Material of tube retaining claw	High-alloy stainless steel