


# Air line lubricator LOE-1/2-D-MAXI

Part number: 186480

FESTO

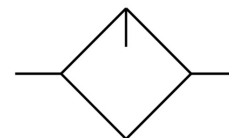

## Data sheet

| Feature                                   | Value                                                              |
|-------------------------------------------|--------------------------------------------------------------------|
| Size                                      | Maxi                                                               |
| Type code                                 | LOE                                                                |
| Series                                    | D                                                                  |
| Mounting position                         | Vertical +/- 5°                                                    |
| Structural design                         | Proportional standard oil mist lubricator                          |
| Max. oil capacity                         | 190 cm³                                                            |
| Bowl guard                                | Metal bowl guard                                                   |
| Symbol                                    | 00991532                                                           |
| Operating pressure                        | 0 bar ... 16 bar                                                   |
| Minimum flow rate for lubricator function | 10 l/min                                                           |
| Standard nominal flow rate                | 8300 l/min                                                         |
| Operating medium                          | Compressed air as per ISO 8573-1:2010 [7:4:4]<br>Inert gas         |
| Information on operating and pilot media  | Operation with oil lubrication possible (required for further use) |
| Corrosion resistance class (CRC)          | 2 - Moderate corrosion stress                                      |
| Storage temperature                       | -10 °C ... 60 °C                                                   |
| Air quality class at the output           | Compressed air as per ISO 8573-1:2010 [7:4:-]<br>Inert gas         |
| Temperature of medium                     | -10 °C ... 60 °C                                                   |
| Ambient temperature                       | -10 °C ... 60 °C                                                   |
| Product weight                            | 1100 g                                                             |
| Type of mounting                          | With accessories                                                   |
| Pneumatic connection 1                    | G1/2                                                               |
| Pneumatic connection 2                    | G1/2                                                               |
| Note on materials                         | RoHS-compliant                                                     |
| Material of bowl                          | PC                                                                 |