
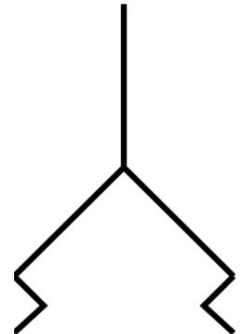


# Vacuum suction cup

## ESS-20-SNA

Part number: 189298

FESTO

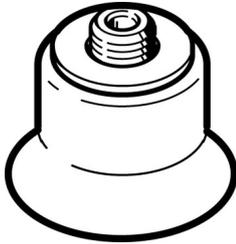

## Data sheet

Feature	Value
Min. workpiece radius	60 mm
Nominal width	3 mm
Suction cup diameter	20 mm
Suction cup volume	0.318 cm <sup>3</sup>
Type code	ESS
Connection position	Top
Mounting position	Any
Special features	Anti-static
Symbol	00991485
Classification of suction cup holder	Size 4
Suction cup shape	Round, flat
Operating pressure	0 bar ... 0.95 bar
Nominal operating pressure	-0.7 bar
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:::]
Corrosion resistance class (CRC)	1 - Low corrosion stress
For use in the food industry	See supplementary material information
Ambient temperature	-10 °C ... 70 °C
Holding force at nominal operating pressure	16.3 N
Lateral force at nominal operating pressure	14.5 N
Product weight	6.4 g
Type of mounting	Via vacuum connection
Vacuum connection	M6
Color	Black/white dot
Shore hardness	50 +/- 5
Material of screwed trunnion	Brass, nickel-plated Steel, galvanized and chrome-plated
Note on materials	Free of copper and PTFE RoHS-compliant
Suction cup material	BR