


# Vacuum suction cup

## ESS-150-SN

Part number: 189326

FESTO

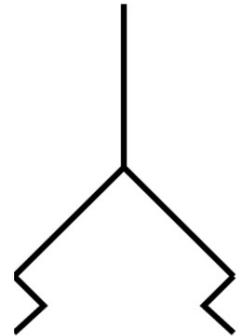

## Data sheet

Feature	Value
Min. workpiece radius	480 mm
Nominal width	10 mm
Suction cup diameter	150 mm
Suction cup volume	173.826 cm <sup>3</sup>
Type code	ESS
Connection position	Top
Mounting position	Any
Symbol	00991485
Classification of suction cup holder	Size 6
Suction cup shape	Round, flat
Operating pressure	0 bar ... 0.95 bar
Nominal operating pressure	-0.7 bar
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7::-:]
Corrosion resistance class (CRC)	1 - Low corrosion stress
For use in the food industry	See supplementary material information
Ambient temperature	-10 °C ... 70 °C
Holding force at nominal operating pressure	900 N
Lateral force at nominal operating pressure	675 N
Product weight	719 g
Type of mounting	Via vacuum connection
Vacuum connection	M20x2
Color	Black
Shore hardness	50 +/- 5
Material of screwed trunnion	NBR Steel, nickel-plated Steel, galvanized and chrome-plated
Note on materials	Free of copper and PTFE RoHS-compliant
Suction cup material	NBR