
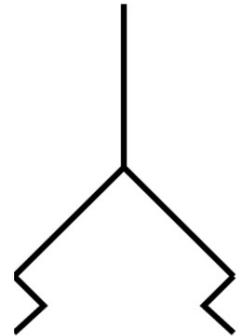


# Vacuum suction cup ESS-80-EF

Part number: 189361

FESTO

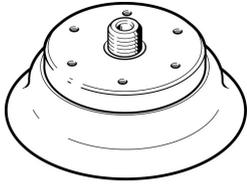

## Data sheet

Feature	Value
Min. workpiece radius	160 mm
Nominal width	6 mm
Suction cup diameter	80 mm
Suction cup volume	51.61 cm <sup>3</sup>
Type code	ESS
Connection position	Top
Mounting position	Any
Symbol	00991485
Classification of suction cup holder	Size 5
Suction cup shape	Round, extra-deep
Operating pressure	0 bar ... 0.95 bar
Nominal operating pressure	-0.7 bar
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7::-:]
Corrosion resistance class (CRC)	1 - Low corrosion stress
For use in the food industry	See supplementary material information
Ambient temperature	-10 °C ... 200 °C
Holding force at nominal operating pressure	275 N
Lateral force at nominal operating pressure	148.5 N
Product weight	141 g
Type of mounting	Via vacuum connection
Vacuum connection	M10
Color	Gray
Shore hardness	60 +/- 5
Material of screwed trunnion	POM Steel, nickel-plated Steel, galvanized and chrome-plated
Note on materials	Free of copper and PTFE RoHS-compliant
Suction cup material	FPM