


Vacuum suction cup ESS-50-BU

Part number: 189391

FESTO

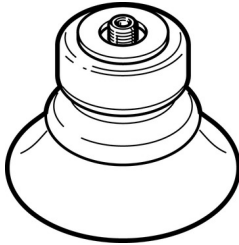

Data sheet

Feature	Value
Suction cup height compensation	11 mm
Min. workpiece radius	150 mm
Nominal width	3 mm
Suction cup diameter	50 mm
Suction cup volume	14.23 cm ³
Type code	ESS
Connection position	Top
Mounting position	Any
Symbol	00991485
Classification of suction cup holder	Size 4
Suction cup shape	Round bellows, 1.5 convolutions
Operating pressure	0 bar ... 0.95 bar
Nominal operating pressure	-0.7 bar
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:::]
Corrosion resistance class (CRC)	1 - Low corrosion stress
For use in the food industry	See supplementary material information
Ambient temperature	-20 °C ... 60 °C
Holding force at nominal operating pressure	72.6 N
Lateral force at nominal operating pressure	47 N
Product weight	24.7 g
Type of mounting	Via vacuum connection
Vacuum connection	M6
Color	Blue
Shore hardness	60 +/- 5
Material of screwed trunnion	Wrought aluminum alloy, nickel-plated Brass, nickel-plated Steel, galvanized and chrome-plated
Note on materials	Free of copper and PTFE Contains paint-wetting impairment substances RoHS-compliant
Suction cup material	PUR