


Vacuum suction cup

ESS-30-CS

Part number: 189403

FESTO

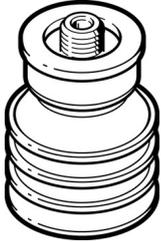

Data sheet

Feature	Value
Suction cup height compensation	10.5 mm
Min. workpiece radius	80 mm
Nominal width	3 mm
Suction cup diameter	30 mm
Suction cup volume	9.47 cm ³
Type code	ESS
Connection position	Top
Mounting position	Any
Symbol	00991485
Classification of suction cup holder	Size 4
Suction cup shape	Round bellows, 3.5 convolutions
Operating pressure	0 bar ... 0.95 bar
Nominal operating pressure	-0.7 bar
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7::-]
Corrosion resistance class (CRC)	1 - Low corrosion stress
For use in the food industry	See supplementary material information
Ambient temperature	-30 °C ... 180 °C
Holding force at nominal operating pressure	20.8 N
Lateral force at nominal operating pressure	11 N
Product weight	12.2 g
Type of mounting	Via vacuum connection
Vacuum connection	M6
Color	Transparent
Shore hardness	50 +/- 5
Material of screwed trunnion	Brass, nickel-plated Steel, galvanized and chrome-plated
Note on materials	Free of copper and PTFE Contains paint-wetting impairment substances RoHS-compliant
Suction cup material	VMQ (silicone)