


Non return valve HA-3/8-QS-3/8-U

Part number: 190855

FESTO

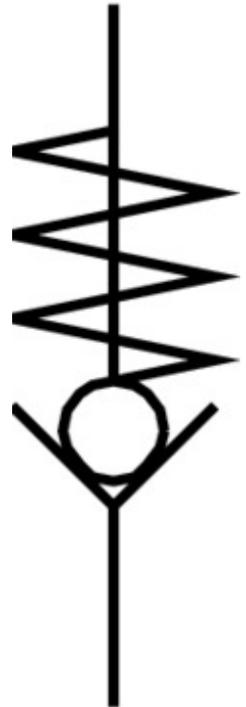

Data sheet

Feature	Value
Type code	HA
Valve function	Non-return function
Pneumatic connection 1	3/8 NPT
Pneumatic connection 2	QS-3/8
Type of mounting	Screw-in
Standard nominal flow rate	1700 l/min
Operating pressure	-1 bar ... 10 bar
Ambient temperature	0 °C ... 60 °C
Housing material	Brass
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Symbol	00991455
Min. differential pressure, opening	0.1 bar
Min. differential pressure, closing	0.2 bar
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Product weight	48 g
Note on materials	RoHS-compliant