


Vacuum cup without connector ESV-30-SNA

Part number: 190988

FESTO

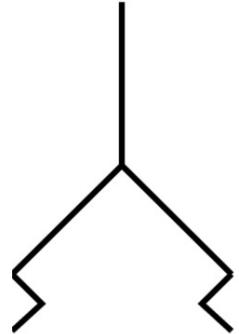

Data sheet

Feature	Value
Min. workpiece radius	110 mm
Suction cup diameter	30 mm
Suction cup volume	0.867 cm ³
Type code	ESV
Connection position	Top
Mounting position	Any
Special features	Anti-static
Symbol	00991485
Suction cup shape	Round, flat
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7::-]
For use in the food industry	See supplementary material information
Ambient temperature	-10 °C ... 70 °C
Holding force at nominal operating pressure	40.8 N
Product weight	2.7 g
Color	Black/white dot
Shore hardness	50 +/- 5
Note on materials	Free of copper and PTFE RoHS-compliant
Suction cup material	BR