


Vacuum cup without connector ESV-100-EF

Part number: 191050

FESTO

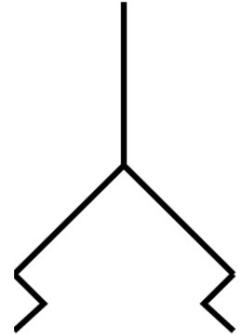

Data sheet

| Feature | Value |
|---|--|
| Min. workpiece radius | 200 mm |
| Suction cup diameter | 100 mm |
| Suction cup volume | 79.812 cm ³ |
| Type code | ESV |
| Connection position | Top |
| Mounting position | Any |
| Symbol | 00991485 |
| Suction cup shape | Round, extra-deep |
| Operating medium | Atmospheric air based on ISO 8573-1:2010 [7:-:-] |
| For use in the food industry | See supplementary material information |
| Ambient temperature | -10 °C ... 200 °C |
| Holding force at nominal operating pressure | 440.8 N |
| Product weight | 65 g |
| Color | Gray |
| Shore hardness | 60 +/- 5 |
| Note on materials | Free of copper and PTFE RoHS-compliant |
| Suction cup material | FPM |