


# Vacuum cup without connector ESV-40-BS

Part number: 191062

FESTO

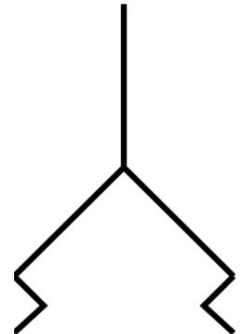

## Data sheet

Feature	Value
Suction cup height compensation	9.5 mm
Min. workpiece radius	90 mm
Suction cup diameter	40 mm
Suction cup volume	11.699 cm <sup>3</sup>
Type code	ESV
Connection position	Top
Mounting position	Any
Symbol	00991485
Suction cup shape	Round bellows, 1.5 convolutions
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7::-]
For use in the food industry	See supplementary material information
Ambient temperature	-30 °C ... 180 °C
Holding force at nominal operating pressure	52.3 N
Product weight	9.8 g
Color	Transparent
Shore hardness	50 +/- 5
Note on materials	Free of copper and PTFE Contains paint-wetting impairment substances RoHS-compliant
Suction cup material	VMQ (silicone)