


Vacuum cup without connector ESV-50-BN

Part number: 191063

FESTO

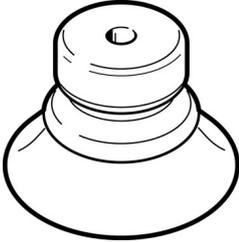

Data sheet

Feature	Value
Suction cup height compensation	11 mm
Min. workpiece radius	150 mm
Suction cup diameter	50 mm
Suction cup volume	14.23 cm ³
Type code	ESV
Connection position	Top
Mounting position	Any
Symbol	00991485
Suction cup shape	Round bellows, 1.5 convolutions
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7::-]
For use in the food industry	See supplementary material information
Ambient temperature	-10 °C ... 70 °C
Holding force at nominal operating pressure	72.6 N
Product weight	13.9 g
Color	Black
Shore hardness	50 +/- 5
Note on materials	Free of copper and PTFE RoHS-compliant
Suction cup material	NBR