


# Vacuum filter ESF-3

Part number: 191202

FESTO

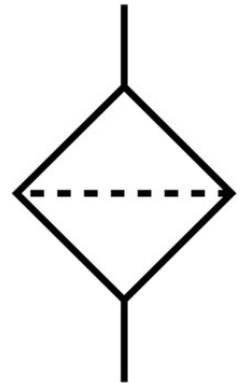

## Data sheet

Feature	Value
Type code	ESF
Mounting position	Any
Grade of filtration	10 µm
Symbol	00991483
Operating pressure	-0.95 bar ... 4 bar
Flow rate at negative pressure = -0.75 bar	100 l/min
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7::-]
Corrosion resistance class (CRC)	1 - Low corrosion stress
Ambient temperature	0 °C ... 60 °C
Product weight	9 g
Type of mounting	With external thread Via vacuum connection
Pneumatic connection	M4
Vacuum connection	M4
Note on materials	Free of copper and PTFE RoHS-compliant
Seals material	NBR
Compressed air filter material	PVF
Housing material	Aluminum Brass, nickel-plated