


# Air preparation unit FRC-1/2-D-5M-DI-MAXI

Part number: 192406

FESTO



## Data sheet

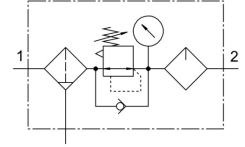

Feature	Value
Size	Maxi
Type code	FRC
Series	D
Actuator lock	Rotary knob with detent
Mounting position	Vertical +/- 5°
Condensate drain	Manually rotating
Structural design	Filter regulator with pressure gauge Proportional standard oil mist lubricator
Max. condensate volume	43 ml
Grade of filtration	5 µm
Bowl guard	Metal bowl guard
Symbol	00991761
Pressure gauge	with pressure gauge
Operating pressure	1 bar ... 16 bar
Pressure regulation range	0.5 bar ... 12 bar
Max. pressure hysteresis	0.4 bar
Standard nominal flow rate	3000 l/min
Maritime classification	See certificate
Operating medium	Compressed air as per ISO 8573-1:2010 [-:--]
Temperature of medium	-10 °C ... 60 °C
Ambient temperature	-10 °C ... 60 °C
Product weight	2670 g
Type of mounting	Line installation
Pneumatic connection 1	G1/2
Pneumatic connection 2	G1/2
Housing material	Die-cast zinc
Material of bowl	PC