


Mounting plate VN-T3-BP-NRH

Part number: 193641

FESTO

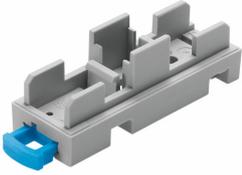

Data sheet

Feature	Value
Type code	VN
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Ambient temperature	0 °C ... 60 °C
Max. tightening torque	0.5 Nm
Product weight	3.5 g
Type of mounting	With through-hole With H-rail
Note on materials	Free of copper and PTFE
Plate material	POM-reinforced
Gate valve material	POM