


Bellow cylinder EB-385-115

Part number: 193789

FESTO

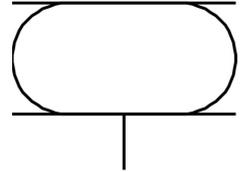

Data sheet

Feature	Value
Size	385
Required installation \varnothing	400 mm
Stroke	115 mm
Max. height, advanced	175 mm
Max. angle of inclination	15 deg
Max. offset	10 mm
Min. installation height	51 mm
Type code	EB
Mode of operation	Single-acting
Symbol	00991205
Operating pressure	0 bar ... 8 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [:-:4]
Information on operating and pilot media	Operation with oil lubrication not possible
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Ambient temperature	-40 °C ... 70 °C
Resetting force	300 N
Product weight	5900 g
Type of mounting	With internal thread
Pneumatic connection	G1/4
Note on materials	Free of copper and PTFE RoHS-compliant
Bellows material	NR/BR
Housing material	Steel Galvanized