


Manifold

MHA1-PR10-3-M3-PI

Part number: 197226

FESTO

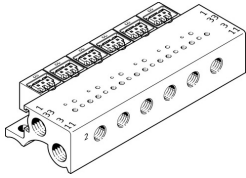

Data sheet

Feature	Value
Type code	MHA1-PR10
Max. no. of valve positions	10
Operating pressure	0 bar ... 8 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	1 - Low corrosion stress
Ambient temperature	-10 °C ... 60 °C
Sub-base mounting type	With through-hole
Pneumatic valve mounting type	With internal thread
Pneumatic connection 1	M7
Pneumatic connection 2	M3
Pneumatic connection 3	M7
Material of sub-base	Wrought aluminum alloy