


# Manifold MHA1-P2-2-M3-PI

Part number: 197227

FESTO

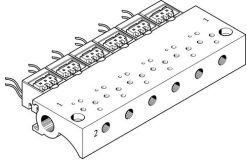

## Data sheet

Feature	Value
Type code	MHA1-P2
Max. no. of valve positions	2
Operating pressure	0 bar ... 8 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	1 - Low corrosion stress
Ambient temperature	-10 °C ... 60 °C
Sub-base mounting type	With through-hole
Pneumatic valve mounting type	With internal thread
Pneumatic connection 1	M7
Pneumatic connection 2	M3
Material of sub-base	Wrought aluminum alloy