


Connection block MHP1-PR6-3-PI-D9

Part number: 197234

FESTO

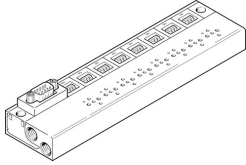

Data sheet

Feature	Value
Type code	MHP1-PR6
Max. no. of valve positions	6
Operating pressure	0 bar ... 8 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	1 - Low corrosion stress
Ambient temperature	-10 °C ... 60 °C
Sub-base mounting type	With through-hole
Pneumatic valve mounting type	With internal thread
Pneumatic connection 1	M7
Pneumatic connection 3	M7
Material of sub-base	Wrought aluminum alloy