


Manifold
MHA1-PR2-3-M3-PI-PCB
Part number: 197247

FESTO

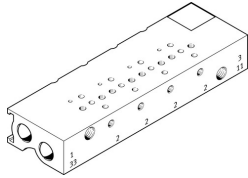

Data sheet

Feature	Value
Type code	MHA1-PR2
Max. no. of valve positions	2
Operating pressure	0 bar ... 8 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Ambient temperature	0 °C ... 40 °C
Pneumatic valve mounting type	With internal thread
Pneumatic connection 1	M5
Pneumatic connection 2	M3
Pneumatic connection 3	M5
Material of sub-base	Wrought aluminum alloy