


# Power supply unit CACN-11A-7-20

Part number: 2247685

FESTO

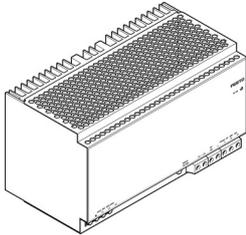

## Data sheet

Feature	Value
Width	125 mm
Height	130 mm
Length	240 mm
Type code	CACN
Mounting position	Free convection
Primary supply	3-phase
Input current	2.3 - 1.9 A
Nominal output voltage DC	48 V
Nominal output current	20 A
Input voltage range AC	400 V ... 500 V
Power failure buffering	50 ms
Mains frequency	45 Hz ... 65 Hz
Certification	C-Tick c UL us - Listed (OL)
CE marking (see declaration of conformity)	As per EU EMC directive As per EU low voltage directive
LABS conformity	VDMA24364 zone III
Storage temperature	-40 °C ... 85 °C
Relative air humidity	95 %
Degree of protection	IP20
Ambient temperature	-25 °C ... 70 °C
Product weight	3500 g
Type of mounting	With H-rail
Note on materials	RoHS-compliant