


# Axial kit EAMM-A-D32-40G-S1

Part number: 2256396

FESTO

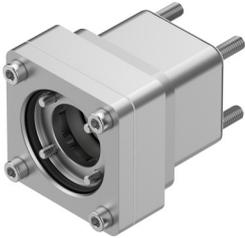

## Data sheet

Feature	Value
Type code	EAMM-A
Mounting position	Any
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP65
Ambient temperature	-10 °C ... 60 °C
Transferable torque	6.5 Nm
Product weight	420 g
Interface code, actuator	D32A D32B
Interface code, motor in	40G
Note on materials	Contains paint-wetting impairment substances RoHS-compliant