


Axial kit EAMM-A-D32-67A-S1

Part number: 2256397

FESTO

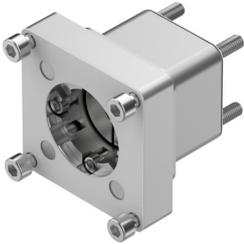

Data sheet

| Feature | Value |
|--------------------------|--|
| Type code | EAMM-A |
| Mounting position | Any |
| Storage temperature | -25 °C ... 60 °C |
| Relative air humidity | 0 - 95 % |
| Degree of protection | IP65 |
| Ambient temperature | -10 °C ... 60 °C |
| Transferable torque | 6.5 Nm |
| Product weight | 410 g |
| Interface code, actuator | D32A D32B |
| Interface code, motor in | 67A |
| Note on materials | Contains paint-wetting impairment substances RoHS-compliant |