


Rotary actuator DRRD-12-180-FH-PA

Part number: 2282067

FESTO

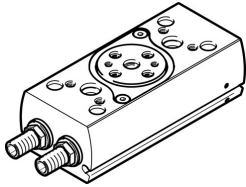

Data sheet

Feature	Value
Size	12
Cushioning angle	32 deg
Adjustment range of swivel angle, both sides	+10 /-100 deg
Swivel angle	180 deg
Type code	DRRD
Cushioning	Elastic cushioning rings/pads at both ends
Mounting position	Any
Structural design	Gear rack/pinion
Position sensing	For proximity sensor
Symbol	00991265
Operating pressure	0.3 MPa ... 0.8 MPa
Operating pressure	3 bar ... 8 bar
Mode of operation	Double-acting
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Ambient temperature	-10 °C ... 60 °C
Theoretical torque at 6 bar	0.8 Nm
Permissible mass moment of inertia	0.008 kgm ²
Product weight	380 g
Type of mounting	Optionally: With through-hole With internal thread
Pneumatic connection	M5
Note on materials	Contains paint-wetting impairment substances RoHS-compliant
Drive shaft material	High-alloy stainless steel
Seals material	NBR TPE-U(PU)
Housing material	Wrought aluminum alloy Smooth anodized