


**Axial kit**  
**EAMM-A-P6-38A-67A**  
Part number: 2297641

**FESTO**

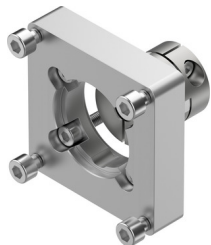

**Data sheet**

| Feature                          | Value            |
|----------------------------------|------------------|
| Type code                        | EAMM-A           |
| Mounting position                | Any              |
| Storage temperature              | -25 °C ... 60 °C |
| Relative air humidity            | 0 - 95 %         |
| Degree of protection             | IP40             |
| Ambient temperature              | -10 °C ... 60 °C |
| Transferable torque              | 6.5 Nm           |
| Product weight                   | 230 g            |
| Interface code, actuator         | P6-38A           |
| Interface code, motor in         | 67A              |
| Interface code, coupling housing | 38A              |
| Note on materials                | RoHS-compliant   |