


Quick coupling EAMC-16-20-3-8

Part number: 2310368

FESTO

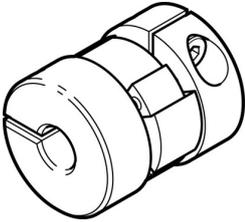

Data sheet

| Feature | Value |
|------------------------|------------------------|
| Diameter of holder 1 | 3 mm |
| Diameter of holder 2 | 8 mm |
| Size | 16 |
| Nominal length | 20 mm |
| Type code | EAMC |
| Mounting position | Any |
| Max. rotational speed | 10000 1/min |
| Storage temperature | -25 °C ... 60 °C |
| Relative air humidity | 0 - 95 % |
| Ambient temperature | -25 °C ... 60 °C |
| Mass moment of inertia | 0.28 kgmm ² |
| Transferable torque | 0.2 Nm |
| Product weight | 8 g |
| Note on materials | RoHS-compliant |