


Pneumatic shock absorber DYSC-20-18-Y1F

Part number: 2479149

FESTO

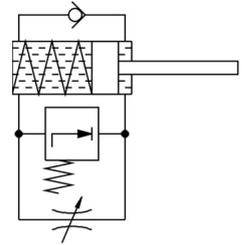

Data sheet

Feature	Value
Size	20
Stroke	18 mm
Type code	DYSC
Cushioning	Self-adjusting
Mounting position	Any
Position sensing	None
Symbol	00991497
Max. impact velocity	3 m/s
Reset time at room temperature	0.3 s
Reset time at min. ambient temperature	1 s
Mode of operation	Single-acting Pushing
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Ambient temperature	-10 °C ... 80 °C
Cushioning length	16 mm
Max. stop force	3000 N
Max. energy absorption per stroke	38 J
Max. energy absorption per hour	80000 J
Max. residual energy	0.32 J
Resetting force	10 N
Product weight	370 g
Type of mounting	With lock nut
Note on materials	Free of copper and PTFE RoHS-compliant
Seals material	NBR
Housing material	Steel Galvanized
Piston rod material	High-alloy steel