


Sub-base VABP-S3-26V1G-G18-2M-R3

Part number: 2605075

FESTO

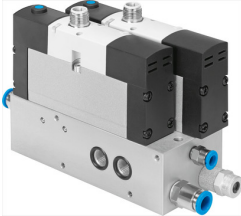

Data sheet

Feature	Value
Width	26 mm
Type code	VABP
Function port 32	G1/8
Function port 34	G1/8
Pneumatic connection 22	G1/8 Sub-base
Pneumatic connection 44	Sub-base G1/8
Mounting position	Any
Operating pressure	0 bar ... 16 bar
Pilot pressure	3 bar ... 8 bar
Standard nominal flow rate	800 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [6:4:4]
Corrosion resistance class (CRC)	0 - No corrosion stress
Temperature of medium	0 °C ... 50 °C
Ambient temperature	0 °C ... 50 °C
Product weight	1200 g
Pilot air port 14	M5
Pneumatic connection 2	G1/8
Pneumatic connection 4	G1/8
Note on materials	RoHS-compliant
Manifold rail material	Wrought aluminum alloy
O-ring material	NBR
Material of screws	Steel