



Branching module PMBL-90-HP3-E

Part number: 2663892

FESTO

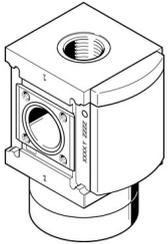

Data sheet

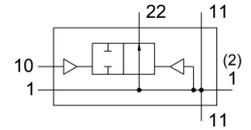

Feature	Value
Size	90
Nominal width DN	36
Type code	PMBL
Series	L
Mounting position	Any
Structural design	Branching module
Symbol	00995259
Operating pressure	0 MPa ... 5 MPa
Operating pressure	0 bar ... 50 bar
Pilot pressure	0 bar ... 50 bar
CE marking (see declaration of conformity)	as per EU pressure equipment directive
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS conformity	VDMA24364 zone III
Storage temperature	-10 °C ... 60 °C
For use in the food industry	See supplementary material information
Temperature of medium	5 °C ... 60 °C
Ambient temperature	5 °C ... 60 °C
Product weight	2600 g
Note on materials	RoHS-compliant
Seals material	NBR PE
Housing material	Wrought aluminum alloy