


Bellow cylinder EB-80-45

Part number: 2748904

FESTO

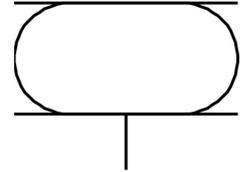

Data sheet

Feature	Value
Size	80
Required installation \varnothing	95 mm
Stroke	45 mm
Max. height, advanced	110 mm
Max. angle of inclination	15 deg
Max. offset	10 mm
Min. installation height	65 mm
Type code	EB
Mode of operation	Single-acting
Symbol	00991205
Operating pressure	0 bar ... 8 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [:-:4]
Information on operating and pilot media	Operation with oil lubrication not possible
Corrosion resistance class (CRC)	0 - No corrosion stress
Ambient temperature	-40 °C ... 70 °C
Resetting force	200 N
Product weight	500 g
Type of mounting	With internal thread
Pneumatic connection	G1/4
Note on materials	Free of copper and PTFE RoHS-compliant
Bellows material	CR
Housing material	Cast aluminum