


Guide unit EAGF-V2-KF-50-400

Part number: 2784184

FESTO

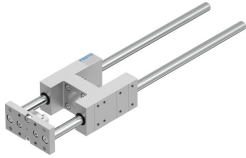

Data sheet

Feature	Value
Size	50
Stroke	400 mm
Reversing backlash	0 µm
Type code	EAGF
Mounting position	Any
Guide	Recirculating ball bearing guide
Structural design	Guide
Corrosion resistance class (CRC)	0 - No corrosion stress
Ambient temperature	-20 °C ... 80 °C
Max. force Fy	1260 N
Max. force Fy static	1600 N
Max. force Fz	1260 N
Max. force Fz static	1600 N
Max. torque Mx	65 Nm
Max. static moment Mx	83 Nm
Max. torque My	70 Nm
Max. static moment My	89 Nm
Max. torque Mz	70 Nm
Max. static moment Mz	89 Nm
Displacement force	15 N
Moving mass	3975 g
Product weight	6019 g
Center of gravity of moving mass with 0 mm stroke	46 mm
Center of gravity of moving mass with 10 mm stroke	4.3 mm
Type of mounting	With internal thread
Note on materials	Free of copper and PTFE RoHS-compliant
Material of guide component	Tempered steel
Housing material	Wrought aluminum alloy Anodized
Material of yoke plate	Steel