


Parallel kit EAMM-U-145-D100-120G-188-S1

Part number: 2803622

FESTO

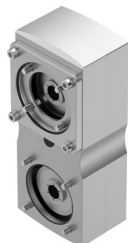

Data sheet

Feature	Value
Size	145
Type code	EAMM-U
Mounting position	Any
Gear ratio	1:1
Max. rotational speed	4000 1/min
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP65
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	2270 kgmm ²
No-load driving torque	2 Nm
Transferable torque	50 Nm
Product weight	12100 g
Note on materials	RoHS-compliant