


Braking resistor CACR-KL2-40-W2000

Part number: 2882343

FESTO

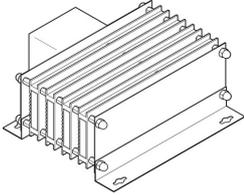

Data sheet

Feature	Value
Size	500
Type code	CACR
Mounting position	Free convection Vertical
Pulse energy braking resistor at 380 V	8000 Ws
Pulse energy braking resistor at 780 V	7200 Ws
Output at 35% duty cycle and 20°C	2000 W
Braking resistor nominal power	800 W
Braking resistor nominal power at 380 V	600 W
Braking resistor nominal power at 780 V	480 W
Resistance value	40 Ohm
Certification	c CSA us (OL) c UL us - Recognized (OL)
LABS conformity	VDMA24364 zone III
Degree of protection	IP65
Ambient temperature	0 °C ... 50 °C
Product weight	2400 g
Type of mounting	Optionally: With through-hole With accessories
Note on materials	Contains paint-wetting impairment substances RoHS-compliant