


Clevis flange SNCS-125-R3

Part number: 2895926

FESTO

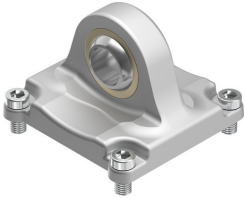

Data sheet

Feature	Value
Size	125
Type code	SNCS
Based on norm	ISO 15552 (previously also VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290)
Variants	High corrosion protection
Corrosion resistance class (CRC)	3 - High corrosion stress
Ambient temperature	-40 °C ... 150 °C
Product weight	1369 g
Note on materials	RoHS-compliant
Mounting material	Wrought aluminum alloy With protective coating
Rod end bearing material	PTFE Stainless steel
Material of screws	High-alloy stainless steel