


Plug socket with cable KMV-1-230AC-2,5

Part number: 30940

FESTO

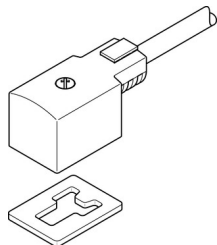

Data sheet

Feature	Value
Type code	KMV
Type of mounting	On air solenoid valve with M3 central screw
Mounting position	Any
Product weight	170 g
Electrical connection	Socket Form B
Nominal operating voltage AC	230 V
Reverse polarity protection	for all electrical connections
Protective earth connection	Available
Cable length	2.5 m
Cable diameter	6 mm
Cable design	3 x 0.75 mm ²
Degree of protection	IP67 as per IEC 60529
Ambient temperature	-20 °C ... 80 °C
CE marking (see declaration of conformity)	As per EU low voltage directive As per EU RoHS directive
Corrosion resistance class (CRC)	1 - Low corrosion stress
Material of cable sheath	PVC
Housing material	PC
Material of pin contacts	Bronze