


# Quick coupling EAMC-67-62-24-25

Part number: 3187895

FESTO

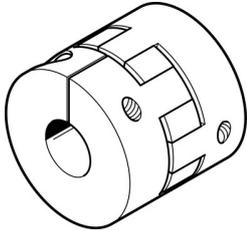

## Data sheet

| Feature                | Value                 |
|------------------------|-----------------------|
| Diameter of holder 1   | 24 mm                 |
| Diameter of holder 2   | 25 mm                 |
| Size                   | 67                    |
| Nominal length         | 62 mm                 |
| Type code              | EAMC                  |
| Mounting position      | Any                   |
| Max. rotational speed  | 4500 1/min            |
| Storage temperature    | -25 °C ... 60 °C      |
| Relative air humidity  | 0 - 95 %              |
| Ambient temperature    | -25 °C ... 60 °C      |
| Mass moment of inertia | 280 kgmm <sup>2</sup> |
| Transferable torque    | 143 Nm                |
| Product weight         | 435 g                 |
| Note on materials      | RoHS-compliant        |