


# Coupling piece KSG-M10X1,25

Part number: 32963

FESTO

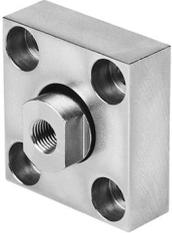

## Data sheet

| Feature                          | Value                                     |
|----------------------------------|---|
| Size                             | M10x1.25                                  |
| Type code                        | KSG                                       |
| Mounting position                | Any                                       |
| Threaded connection              | Internal thread M10x1.25                  |
| Corrosion resistance class (CRC) | 1 - Low corrosion stress                  |
| Ambient temperature              | -40 °C ... 150 °C                         |
| Product weight                   | 229 g                                     |
| Note on materials                | Free of copper and PTFE<br>RoHS-compliant |
| Mounting material                | Steel<br>Galvanized                       |
| Threaded coupling material       | Steel<br>Galvanized                       |