


# Toggle lever valve KH/O-3-PK-3

Part number: 33003

FESTO

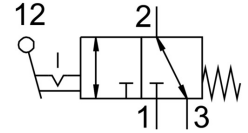

## Data sheet

Feature	Value
Valve function	3/2, open/closed, monostable
Standard nominal flow rate	80 l/min
Pneumatic working port	PK-3
Operating pressure	0 bar ... 8 bar
Structural design	Piston seat
Nominal width	2.5 mm
Type code	KH/O
Type of control	Direct
Symbol	00991285
Ambient temperature	-10 °C ... 60 °C
Actuation force in initial position closed	7.5 N
Actuation force in initial position open	6.5 N
Product weight	20 g
Type of mounting	With through-hole
Pneumatic connection 1	PK-3
Pneumatic connection 2	PK-3
Pneumatic connection 3	PK-3
Seals material	NBR
Housing material	Polymer