


Quick coupling EAMC-40-66-15-22

Part number: 3307627

FESTO

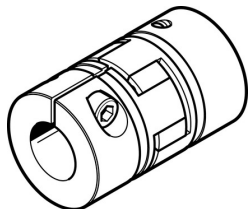

Data sheet

Feature	Value
Diameter of holder 1	15 mm
Diameter of holder 2	22 mm
Size	40
Nominal length	66 mm
Type code	EAMC
Mounting position	Any
Max. rotational speed	6500 1/min
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 °C ... 60 °C
Mass moment of inertia	42.3 kgmm ²
Transferable torque	21 Nm
Product weight	139 g
Note on materials	RoHS-compliant