


Vacuum security valve ISV-3/8

Part number: 33971

FESTO

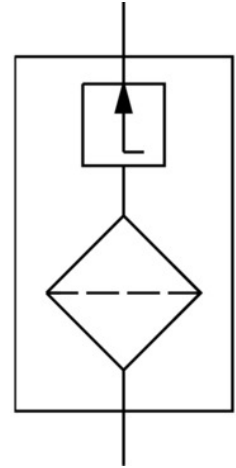

Data sheet

Feature	Value
Size	G3/8
Type code	ISV
Ejector pulse suitability	≤8 MPa
Ejector pulse suitability	8 bar
Mounting position	Any
Symbol	00991481
Operating pressure	-0.095 MPa ... 0 MPa
Operating pressure	-0.95 bar ... 0 bar
Required suction rate at -0.5 bar	1.5 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [7:::]
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Ambient temperature	-10 °C ... 60 °C
Product weight	33 g
Type of mounting	Screw-in
Pneumatic connection 1	G3/8
Pneumatic connection 2	G3/8
Material of spring	High-alloy steel
Compressed air filter material	Wrought aluminum alloy Stainless steel mesh
Housing material	Wrought aluminum alloy
Hollow bolt material	Wrought aluminum alloy
Float material	POM