


Guide unit FENG-63-160-KF

Part number: 34515

FESTO

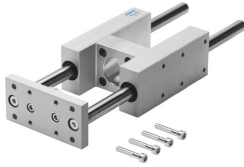

Data sheet

Feature	Value
Size	63
Stroke	160 mm
Type code	FENG
Mounting position	Any
Guide	Recirculating ball bearing guide
Structural design	Guide
Explosion prevention and protection	Zone 1 (ATEX) Zone 2 (ATEX) Zone 21 (ATEX) Zone 22 (ATEX)
Ambient temperature	-20 °C ... 80 °C
Max. force Fy	1260 N
Max. force Fy static	1600 N
Max. force Fz	1260 N
Max. force Fz static	1600 N
Max. torque Mx	75 Nm
Max. static moment Mx	95 Nm
Max. torque My	90 Nm
Max. static moment My	115 Nm
Max. torque Mz	90 Nm
Max. static moment Mz	115 Nm
Displacement force	15 N
Product weight	6194 g
Type of mounting	With internal thread
Note on materials	Free of copper and PTFE RoHS-compliant
Material of guide component	Tempered steel
Housing material	Wrought aluminum alloy, anodized
Material of yoke plate	Wrought aluminum alloy, anodized